


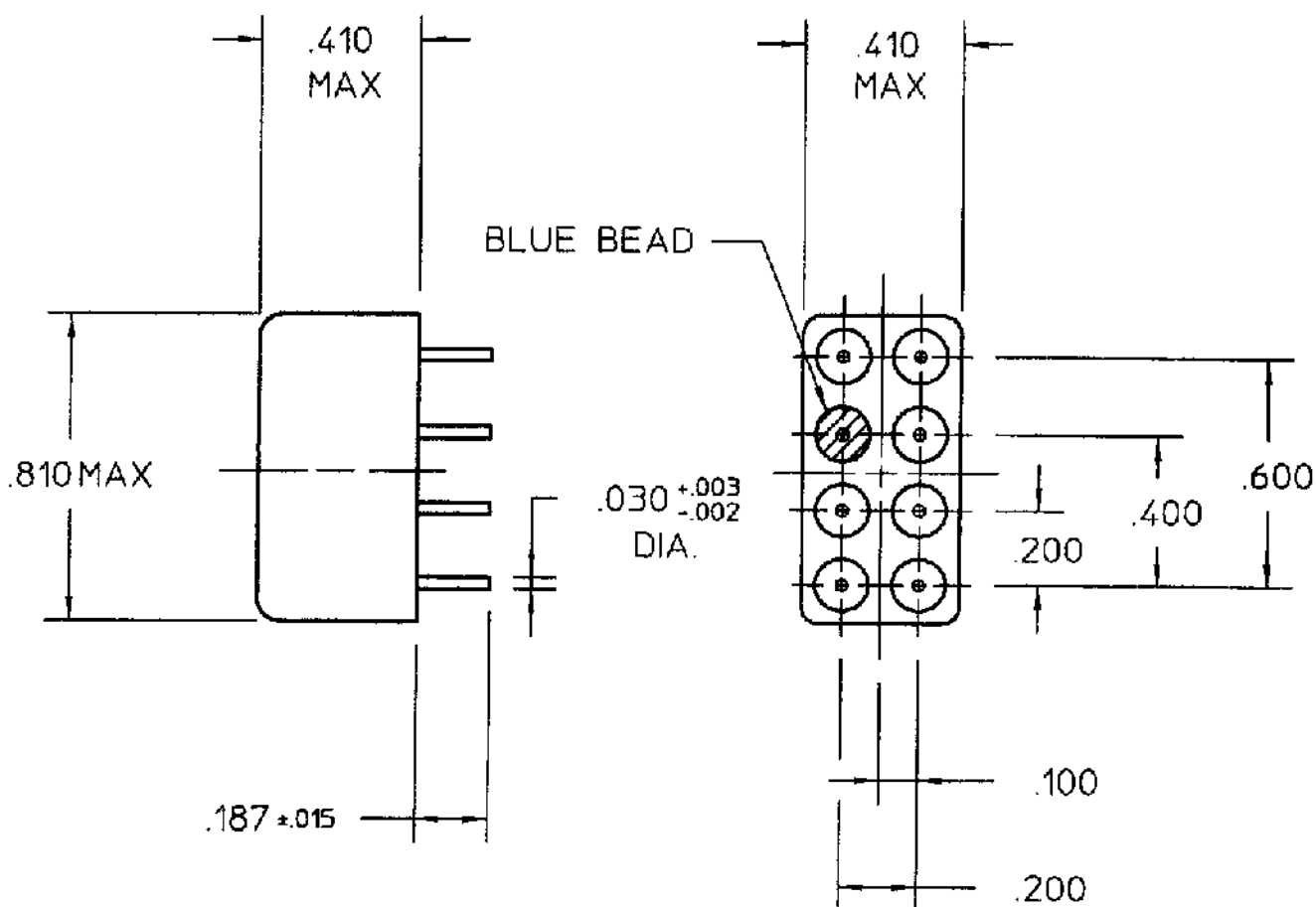

REV. 1

DCO 16539

COIL: @ 25°C
 RESISTANCE 700 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 1.5 VDC


ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX
 RELEASE 2 MS MAX : BOUNCE 3 MS MAX
 DRY CIRCUIT MISS TEST PERFORMED ON
 EACH RELAY

CUST. HI-G
 CUST. NO. 2K-2A-126D REV. "HFW" RELAY

CUSTOMER DATA SHEET

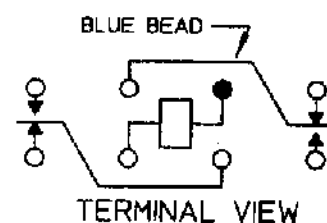

CONTACT RATING: 2A 30 VDC
 RESISTIVE .75A 30 VDC INDUCTIVE
 100,000 OPERATIONS

DR. RB 9/22/92 CK. TLG 10-11-00

CII Technologies™
 advanced control electronic solutions

HFW1201S296