


REV. 0
 DCO 17631

COIL: @ 25°C
 RESISTANCE 310 OHMS ±10%
 NOMINAL VOLTAGE 12 VDC
 MUST OPERATE 6.0 VDC
 MUST RELEASE 3.0 VDC MAX 0.6 VDC MIN

ENVIRONMENT:
 VIBRATION 10 Hz TO 2000 Hz @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE & RELEASE 4 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

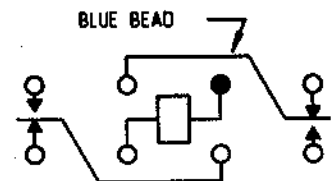

TERMINAL VIEW

CONTACT RATING: 1 AMP 28 VDC
 RESISTIVE 100,000 OPERATIONS

DR. ASB 13 SEP 02 CK *[Signature]* 9/16/02



CUST. QPL
 CUST. NO. M39016/34-011 REV. _____
 MFW RELAY

MFW 1201S09