


1. PART NUMBER AND CHARACTERISTICS

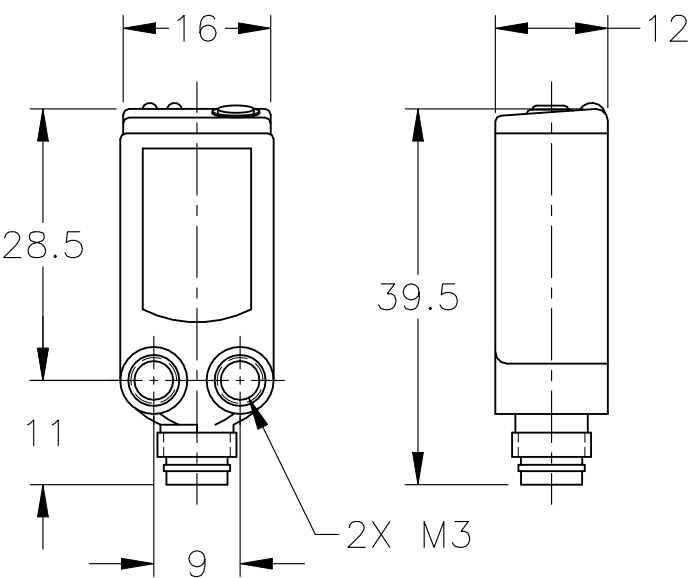

TE Part No	Rev	Switching Output	Switching Mode	Operating Distance Adjustment	Light Spot Diameter @ 50 Distance	Type	Mfr Part No
2030767-1	A	PNP, Q	Light	Potentiometer, 5 revs	5 x 28	WTB4-3P2171	1028123
2030767-2	B	PNP, Q	Dark	Potentiometer, 5 revs	7	WTB4-3F2161	1028107
2030767-3	C	PNP, Q	Light	Teach-in: Single Teach button	7	WTB4-3P2162	1028084

SUPERSEDED BY
2464129-1


- 1.1. All dimensions are nominal unless otherwise specified
1.2. Connection type: 3-pin M8 connector
1.3. Operating temperature: -40° to 60°C
2. RECOMMENDED MANUFACTURER
SICK Group
www.sick.de
or Tyco Electronics Engineering approved equivalent.

COMMERCIAL ITEM SPECIFICATION

MATERIAL	-----
FINISH	-----



 © 2009 Tyco Electronics Corporation, Harrisburg, PA
All International Rights Reserved



DIMENSIONS IN
mm

NO	2030767	REV	D	LOC	B	DIST	31
----	---------	-----	---	-----	---	------	----

D	ECR-23-184613	AS	18AUG2023
C	Add -3	JNB	09JUL09
REV	ENGINEERING CHANGE	CHK	DATE

SHEET
1 OF 1

SENSOR, PROXIMITY SWITCH,
PHOTOELECTRIC,
BACKGROUND SUPPRESSION