


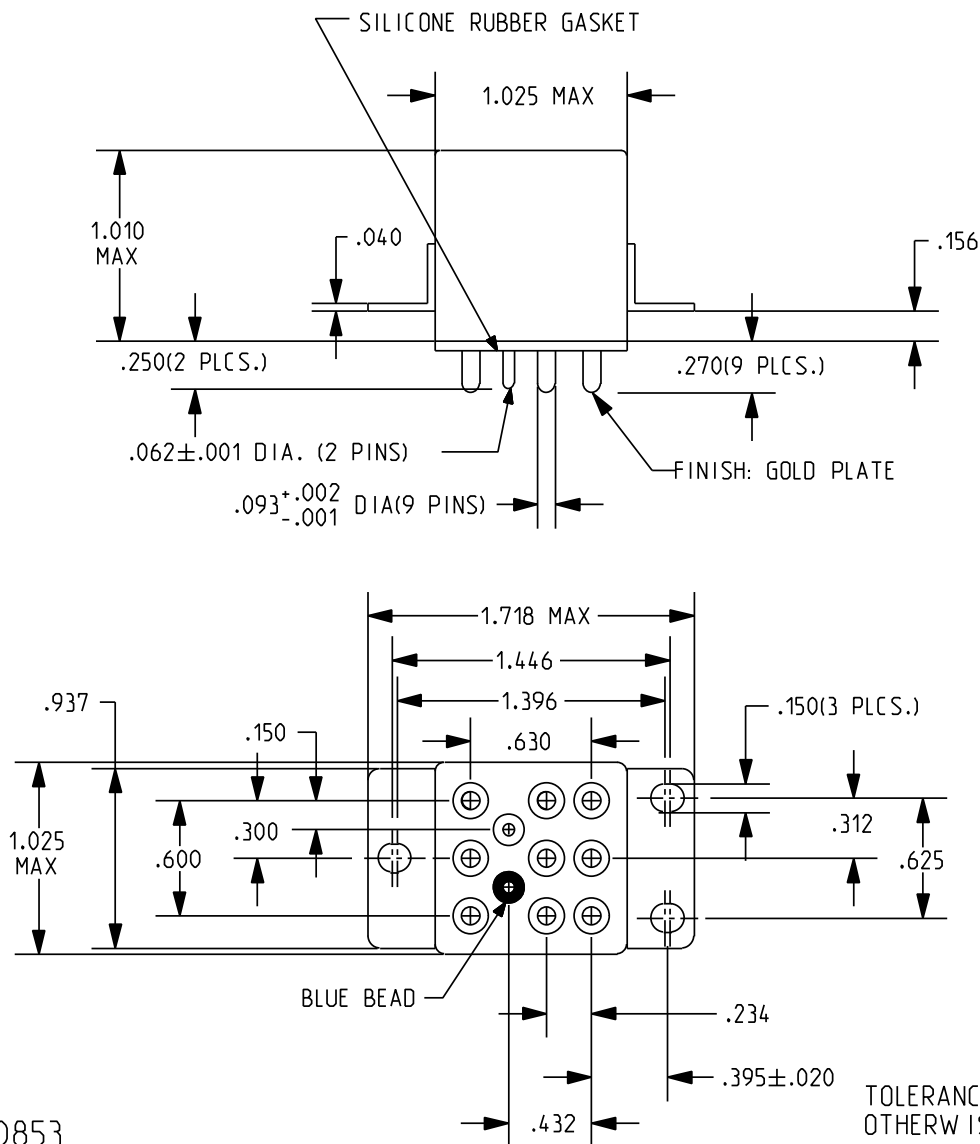

REV. C
DCO 300853


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
RESISTANCE 290 OHMS ±10%
NOMINAL VOLTAGE 28 VDC
MUST OPERATE 13.5 VDC MAX.
TRANSIENT SUPPRESSION - 42 VDC MAX.
MUST RELEASE 6.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
VIBRATION 33 Hz TO 3000 Hz @ 30 g's
SHOCK 200 g's 6 MS. DURATION
TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.
CONTACT BOUNCE 1 MS MAX.
CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

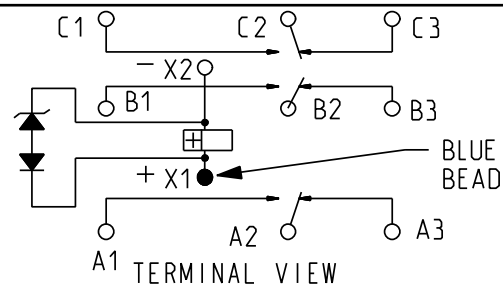

CONTACT RATING:
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
50,000 OPERATIONS

DR. B.D. 10APR2008 CK. J.M.B. 5/14/08

Tyco Electronics

©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG
CUST. NO. ---- REV. N/A

TE NUMBER
3-1617753-9

CII PART NUMBER
FCA-325-AY4