


COIL: @ 25°C	
WINDING #1	WINDING #2
975 OHMS ±10%	975 OHMS ±10%
8.8 mADC MUST OPERATE	8.8 mADC MUST OPERATE
16.0-29.0 VDC NOM. VOLTAGE	16.0-29.0 VDC NOM. VOLTAGE

**CUSTOMER DATA SHEET**

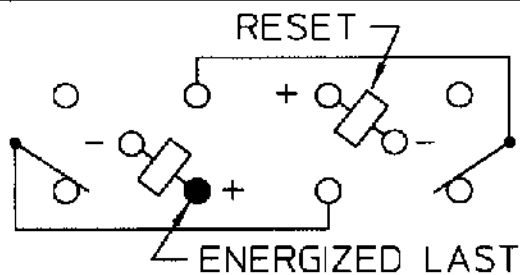

CONTACT RATING: LOW LEVEL TO 2A  
28 VDC RESISTIVE 100,000 OPERATIONS

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 150 g's 11 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: SET AND RESET TIME 4 MS MAX.  
CONTACT BOUNCE 2 MS MAX.

DR. R.B. 3/24/98 CK 3/25/98 *[Signature]*

**COMMUNICATIONS  
 INSTRUMENTS, INC.**

CUST. C. I. I. STD.  
 CUST. NO. \_\_\_\_\_

TYPE "3SAM" RELAY

**3SAM6004M2**