


REV. 0
DCO 63735

COIL: @ 25°C	
SET	RESET
1500 OHMS ±15%	1500 OHMS ±15%
7.1 mADC NOMINAL VOLTAGE	7.1 mADC NOMINAL VOLTAGE
28 VDC MUST OPERATE	28 VDC MUST OPERATE
ENVIRONMENT:	
VIBRATION	10 Hz 3000 Hz 30 g's
SHOCK	150 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES: SET AND RESET TIME 4 MS MAX.	
CONTACT BOUNCE 2 MS MAX.	
CUST. C. I. I. STD.	TYPE '3SAM' RELAY
CUST. NO.	

CUSTOMER DATA SHEET

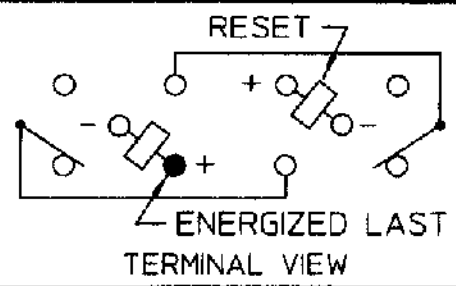

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 1/17/01 CK. 1/17/01



3SAM6154N2