

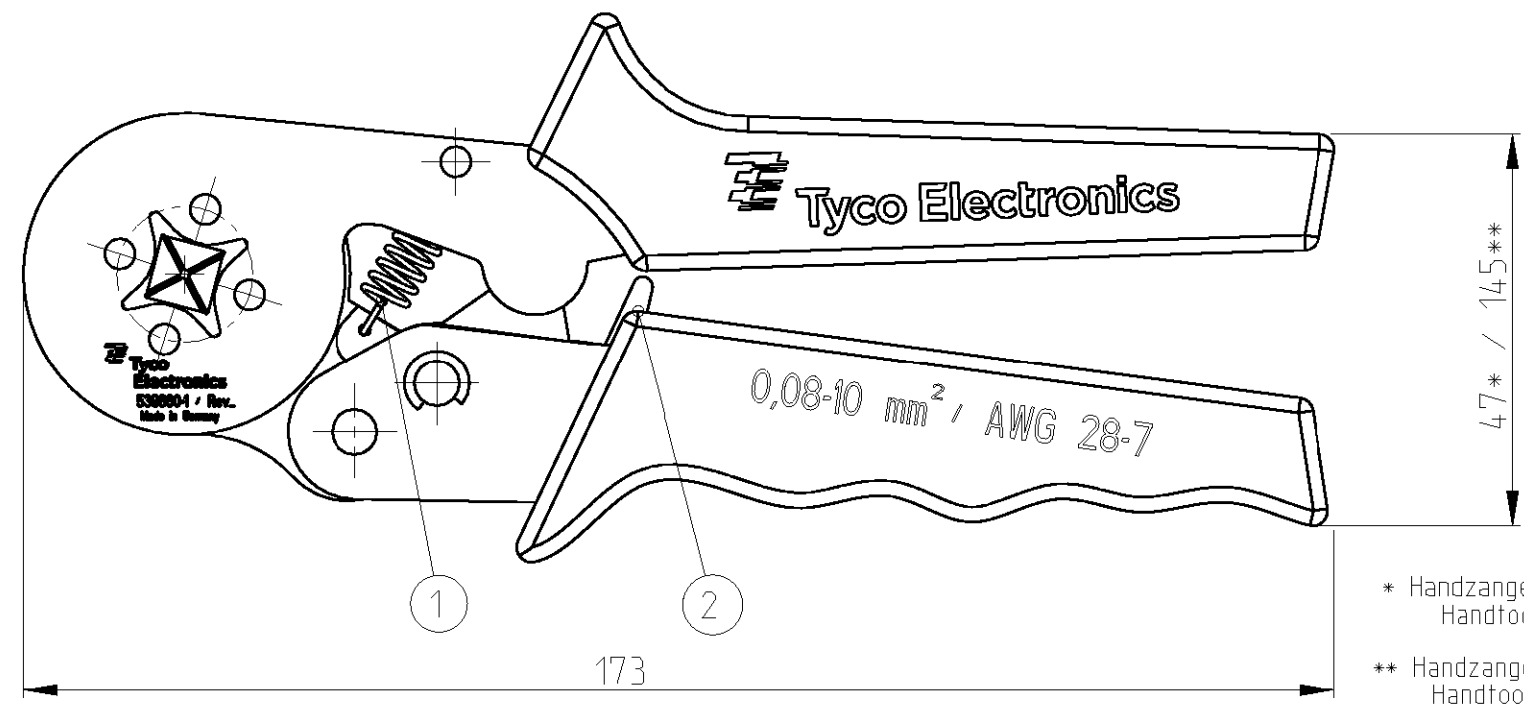


THIS DRAWING IS UNPUBLISHED. RELEASED FOR PUBLICATION 2007
 © COPYRIGHT BY ALL RIGHTS RESERVED.

LOC	DIST	REVISIONS				
P	LTR	DESCRIPTION	DATE	DWN	APVD	
A1	-	B1	REVISED PER ECO-11-005150	28MAR11	RK	HMR

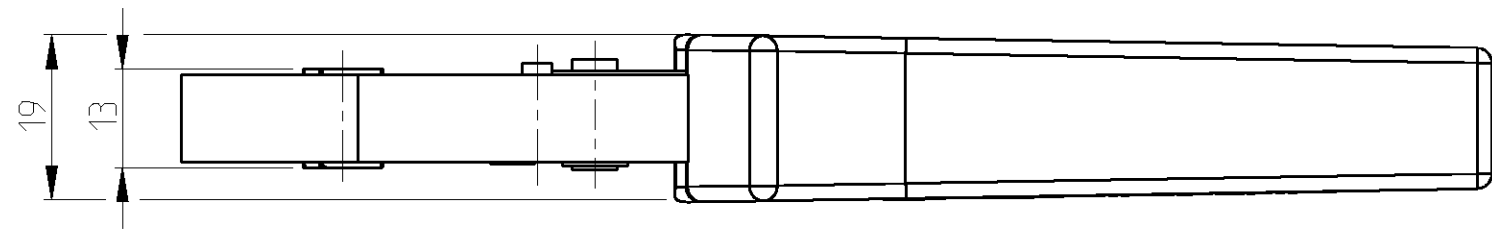

* Handzange geschlossen
Handtool closed
 ** Handzange geoeffnet
Handtool open

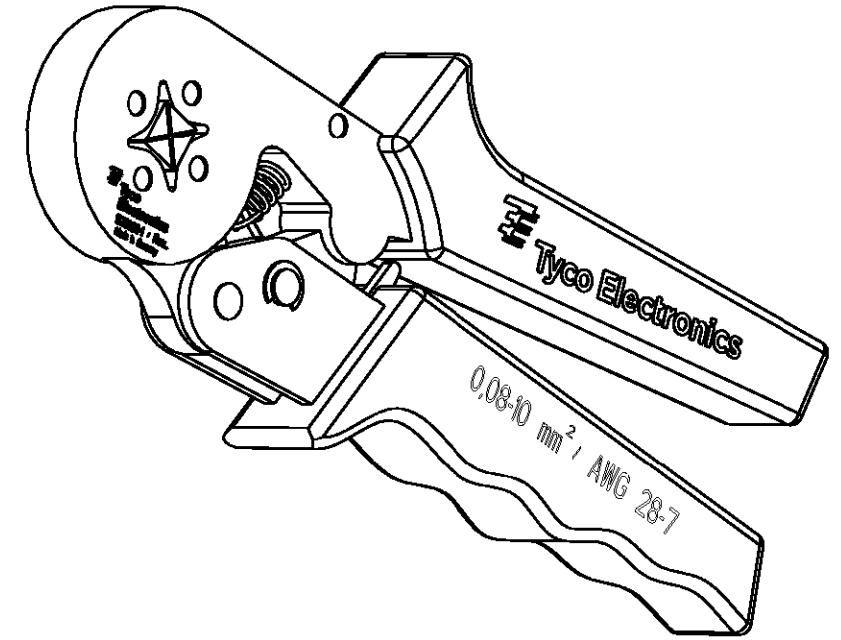

Handzange mit vier profilierten Crimpflaechen. Querschnittsbereich 0,08 - 10 mm²
 Hand tool with four serrated crimp surfaces. Wire size range 0,08 - 10 mm²

Handzange geeignet zum Crimpen von Aderendhuelsen mit und ohne Kunststoffkragen nach DIN 46228 - Teil 1 und Teil 4. Maximale Crimplaenge 13 mm
 Hand tool able to crimp wire ferrules with or without plastic sleeves according to DIN 46228 - Part 1 and Part 4. Maximum crimp length 13 mm

TE Connectivity Aderendhuelsen **TE Connectivity** PN 966066 und 966067 koennen mit dieser Handzange (max. Crimplaenge 13 mm) verarbeitet werden.
TE Connectivity wire ferrules **TE Connectivity** PN 966066 and 966067 can be processed with this hand tool (max. length 13 mm)

Hand tool mit Bedienungsanleitung 411-18232 im Karton verpackt
 Hand tool packed in a card board with instruction sheet 411-18232

Ersatzteile / Spare parts

TE CONNECTIVITY PN	DESCRIPTION	POS.
5-539783-0	Zugfeder/pull spring	2
5-539783-1	Zugfeder/pull spring	1

DIMENSIONS: mm-DIN 7168-m		TOLERANCES UNLESS OTHERWISE SPECIFIED:		DWN U.Reuter 13FEB2002	
		0 PLC ±	1 PLC ±	CHK -	
		2 PLC ±	3 PLC ±	APVD -	
MATERIAL -		4 PLC ±	ANGLES ±	PRODUCT SPEC -	
		FINISH -		APPLICATION SPEC -	NAME Handzange fuer Aderendhuelsen Handtool for Wire Ferrules
				WEIGHT 380 g	SIZE A3
				CUSTOMER DRAWING	CAGE CODE 00779
					DRAWING NO C=539660-1
					RESTRICTED TO -
				SCALE 1	SHEET 1 OF 1
					REV B1