


TWO CONDUCTOR CABLE, RADIATION CROSSLINKED, MODIFIED FLUOROPOLYMER INSULATED,  
150°C, 600 VOLT, LIGHTWEIGHT

The complete requirements for procuring the wire described herein shall consist of this document.

Component wire -  
55A0111

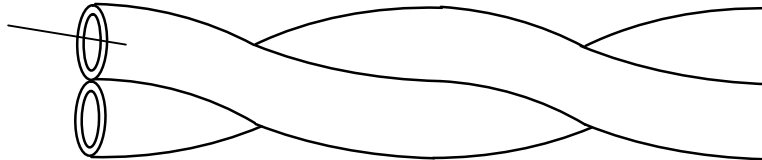

Part Number	Wire Size AWG	Outside Diameter (mm)		Maximum Weight (kg/ km)
		Target	Max	
55CD0299-26-*/*	26	1.62	1.73	4.21

**COLOUR CODE:** The "\*" in the part number shall be replaced by colour code designators with a slash separating component wire colours:  
e.g. 55CD0299-26-2/6, size 26, cores red, blue.

**PERFORMANCE REQUIREMENTS:** This product shall meet all the requirements of the issue in effect of 55A0121 except that:

the lay direction shall be right hand

**APPROVAL:** Electronic sign off - no signatures will appear.