

REV. C
DCO 103073

COIL: @ 25°C	
RESISTANCE	300 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	1.8 VDC


ENVIRONMENT:	
VIBRATION	10 Hz TO 2000 Hz @ 20 g's
SHOCK	50 g's 11 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE & RELEASE 10 MS MAX.
CONTACT BOUNCE 5 MS MAX

CUST. CII STD
CUST. NO. REV.

TE NUMBER
2-1617004-6

CUSTOMER DATA SHEET

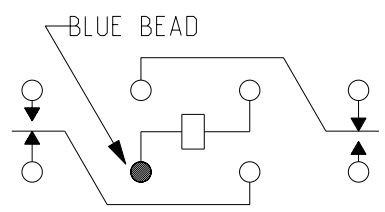

TERMINAL VIEW

CONTACT RATING:	10 AMPS 28 VDC
	5 AMPS 115 VAC/400 Hz RESISTIVE
	100,000 OPERATIONS

DR. PBB 1/5/01

CK. J.M.B 7/15/2013



B07D631BC2