

REV. B  
DCO 300860


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	320 OHMS ±10%
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.	
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.  
CONTACT BOUNCE 1 MS MAX.  
CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

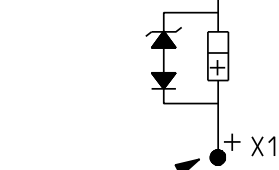

BLUE BEAD  
TERMINAL VIEW

CONTACT RATING: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE  
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08



©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. QPL  
CUST. NO. M6106/19-021 REV. ----

TE NUMBER  
2-1617748-7

CII PART NUMBER

FCA-125-21