


COIL: @ 25°C  
 RESISTANCE \_\_\_\_\_ 290 OHMS ±10%  
 NOMINAL VOLTAGE \_\_\_\_\_ 28.0 VDC  
 MUST OPERATE \_\_\_\_\_ 13.5 VDC MAX.  
 \_\_\_\_\_  
 MUST RELEASE \_\_\_\_\_ 6.5 VDC MAX. 2.3 VDC MIN.

ENVIRONMENT:  
 VIBRATION \_\_\_\_\_ 75 \_\_\_\_\_ Hz TO \_\_\_\_\_ 3000 \_\_\_\_\_ Hz @ \_\_\_\_\_ 20 \_\_\_\_\_ g's  
 SHOCK \_\_\_\_\_ 50 \_\_\_\_\_ g's \_\_\_\_\_ 11 \_\_\_\_\_ MS. DURATION  
 TEMPERATURE \_\_\_\_\_ -70 \_\_\_\_\_ °C TO \_\_\_\_\_ +125 \_\_\_\_\_ °C

NOTES: \_\_\_\_\_ OPERATE AND RELEASE 15 ms MAX. AT 25°C  
 \_\_\_\_\_ CONTACT BOUNCE 1 ms MAX.  
 \_\_\_\_\_ DIELECTRIC 1250 VRMS MAX./60 Hz (1000 VRMS/60 Hz COIL TO CASE)  
 \_\_\_\_\_ COIL TRANSIENT SUPPRESSION 42 VDC MAX.

 
CUSTOMER DATA SHEET

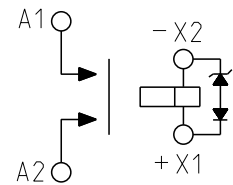

TERMINAL VIEW

CONTACT RATING: \_\_\_\_\_ 50 AMPS 28 VDC.  
 \_\_\_\_\_ RESISTIVE 50,000 OPERATIONS

DR. R.F. 12/10/2012 CK. JMB 12/10/2012



CUST. \_\_\_\_\_ CATALOG ITEM \_\_\_\_\_ TE NUMBER \_\_\_\_\_  
 CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_ 9-1617806-7

FCA-150-KY4