

REV. C  
DCO 300855

TOLERANCES  $\pm .010$ " - UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C	
RESISTANCE	80 OHMS $\pm 10\%$
NOMINAL VOLTAGE	12 VDC
MUST OPERATE	6.5 VDC MAX.
MUST RELEASE	3.3 VDC MAX., 1.2 VDC MIN.

ENVIRONMENT:

VIBRATION	33 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

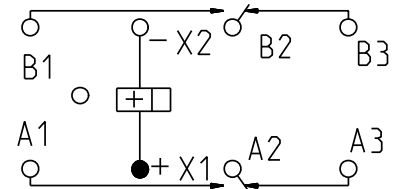

TERMINAL VIEW

CONTACT RATING: 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE.  
100,000 OPERATIONS

DR. B.D. 07MAR2008 CK. J.M.B. 5/14/08

**Tyco Electronics** ©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM \_\_\_\_\_  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

TE NUMBER  
7-1617751-9

CII PART NUMBER  
FCA-210-AY2