

REV. C  
DCO 300855


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C  
 RESISTANCE \_\_\_\_\_ 320 OHMS ±10%  
 NOMINAL VOLTAGE \_\_\_\_\_ 28 VDC  
 MUST OPERATE \_\_\_\_\_ 13.5 VDC MAX.  
 \_\_\_\_\_ TRANSIENT SUPPRESSION - 42 VDC MAX.  
 MUST RELEASE \_\_\_\_\_ 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:  
 VIBRATION \_\_\_\_\_ 33 Hz TO \_\_\_\_\_ 3000 Hz @ \_\_\_\_\_ 30 g's  
 SHOCK \_\_\_\_\_ 200 g's \_\_\_\_\_ 6 MS. DURATION  
 TEMPERATURE \_\_\_\_\_ -70 °C TO \_\_\_\_\_ +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.  
 CONTACT BOUNCE 1 MS MAX.  
 CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

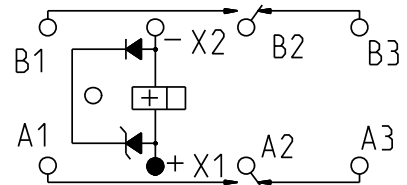

TERMINAL VIEW

CONTACT RATING: \_\_\_\_\_  
 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE.  
 100,000 OPERATIONS

DR. B.D. 07MAR2008 CK. J.M.B. 5/14/08

**Tyco Electronics** ©COPYRIGHT 2005  
 TYCO ELECTRONICS CORPORATION  
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. \_\_\_\_\_ CATALOG ITEM  
 CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

TE NUMBER  
 9-1617751-2

CII PART NUMBER  
 FCA-210-BZ4