


REV. B

DCO-2018-11-16T12_17_29

TOLERANCES $\pm .010''$ - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	320 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
TRANSIENT SUPPRESSION - 42 VDC MAX.	
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

CUSTOMER DATA SHEET

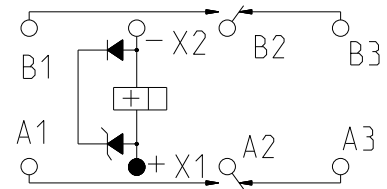

TERMINAL VIEW

ENVIRONMENT:	
VIBRATION	33 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

CONTACT RATING:	
15 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE.	
100,000 OPERATIONS	

NOTES:	OPERATE, RELEASE 10 MS MAX.
CONTACT BOUNCE 1 MS MAX.	
CONTACT BREAK BOUNCE 0.1 MS MAX.	

DR. TWHaynes 14Mar14 CK. JMBaldwin 14Mar14



CUST. CATALOG ITEM	TE NUMBER
CUST. NO. REV.	4-1617752-1

FCA-215-CX4