

REV. C  
DCO 301387

TOLERANCES  $\pm .010$ " - UNLESS  
OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	290 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.	
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.


ENVIRONMENT:

VIBRATION	57 Hz TO 3000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:

OPERATE, RELEASE	15 MS MAX.
CONTACT STABILIZATION	2.5 MS MAX.
CONTACT BOUNCE	1 MS MAX.
CONTACT BREAK BOUNCE	0.1 MS MAX.

CUSTOMER DATA SHEET

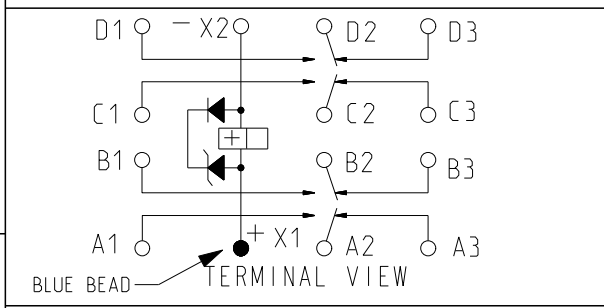

CONTACT RATING:	LOW LEVEL
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE	
100,000 OPERATIONS	

DR. R.F. 21APR2011 CK. M.B. 26APR2011



CUST. QPL  
CUST. NO. M83536/16-024M REV. ----

TE NUMBER  
2-1617754-3

CII PART NUMBER  
FCA-410-1624M