


REV. C  
DCO 300783

TOLERANCES  $\pm .010"$  - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	500 OHMS $\pm 10\%$
NOMINAL VOLTAGE	28 VDC
MUST OPERATE	13.5 VDC MAX.
MUST RELEASE	5.5 VDC MAX., 2.3 VDC MIN.

CUSTOMER DATA SHEET

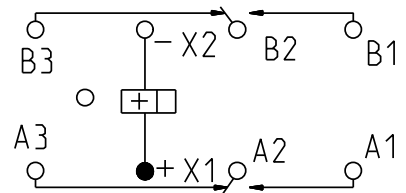

TERMINAL VIEW

ENVIRONMENT:

VIBRATION	70 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 5 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

CONTACT RATING: LOW LEVEL  
TO 5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,  
100,000 OPERATIONS

DR. CK. J.M.B. 3/17/08

B.D. 14MAR2008  
COPYRIGHT 2005  
**Tyco Electronics** TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM \_\_\_\_\_  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

TE NUMBER  
6-1617758-8

C11 PART NUMBER  
FCB-205-AY3