
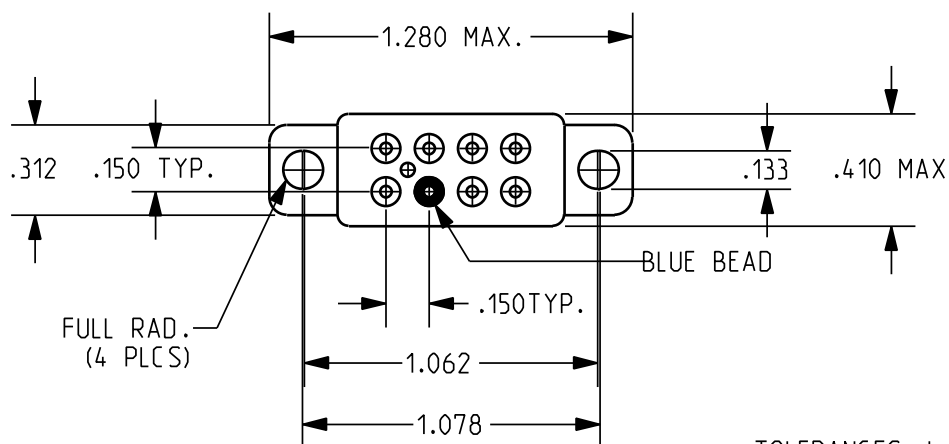


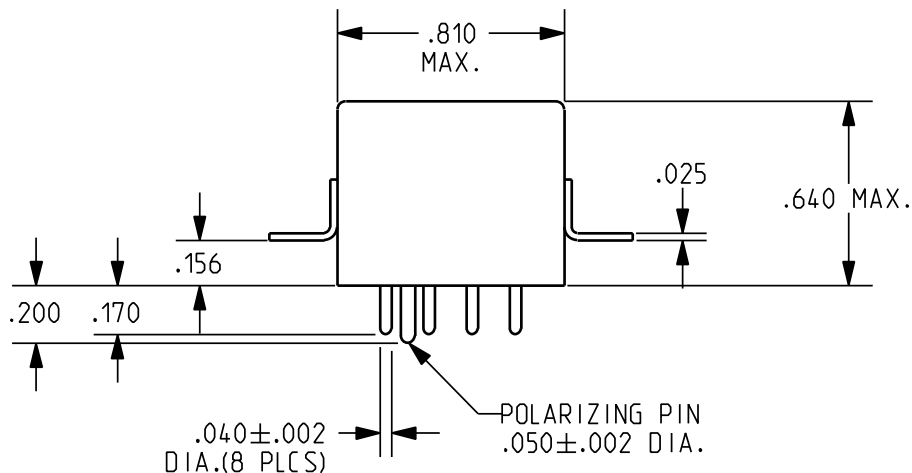

REV. A

DCO 300783

TOLERANCES $\pm .010"$ - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C

RESISTANCE 95 OHMS $\pm 10\%$

NOMINAL VOLTAGE 12 VDC

MUST OPERATE 6.5 VDC MAX.

MUST RELEASE 3.3 VDC MAX., 0.75 VDC MIN.

ENVIRONMENT:

VIBRATION 70 Hz TO 3000 Hz @ 30 g's


SHOCK 200 g's 6 MS. DURATION

TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 5 MS MAX.

CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

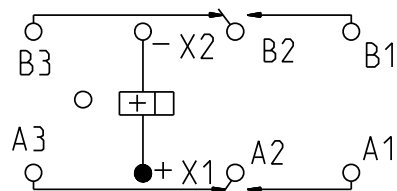

TERMINAL VIEW

CONTACT RATING: LOW LEVEL
TO 5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,
100,000 OPERATIONS

DR. B.D. 11MAR2008

CK. J.M.B. 3/17/08

Tyco Electronics

©COPYRIGHT 2005

TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM

CUST. NO. REV.

TE NUMBER

7-1617758-3

CII PART NUMBER

FCB-205-BY2