


REV. C
DCO 300783

TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	95 OHMS ±10%
NOMINAL VOLTAGE	12 VDC
MUST OPERATE	6.5 VDC MAX.
MUST RELEASE	3.3 VDC MAX., 0.75 VDC MIN.

CUSTOMER DATA SHEET

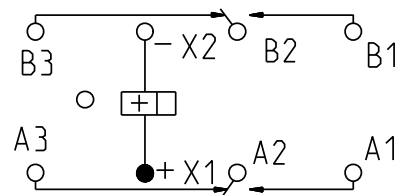

TERMINAL VIEW

ENVIRONMENT:	
VIBRATION	70 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C
NOTES: OPERATE, RELEASE 5 MS MAX.	
CONTACT BOUNCE 1 MS MAX.	

CONTACT RATING: LOW LEVEL
TO 5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE,
100,000 OPERATIONS

DR. B.D. 11MAR2008 CK. J.M.B. 3/17/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM _____
CUST. NO. _____ REV. _____

TE NUMBER
7-1617758-7

CII PART NUMBER
FCB-205-BZ2