

REV. B
DCO 300825

TOLERANCES $\pm .010$ " - UNLESS OTHERWISE SPECIFIED


COIL: @ 25°C	
RESISTANCE	78 OHMS $\pm 10\%$
NOMINAL VOLTAGE	12 VDC
MUST OPERATE	6.6 VDC MAX.
MUST RELEASE	3.3 VDC MAX., 0.75 VDC MIN.

ENVIRONMENT:

VIBRATION	70 Hz TO 3000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 6 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

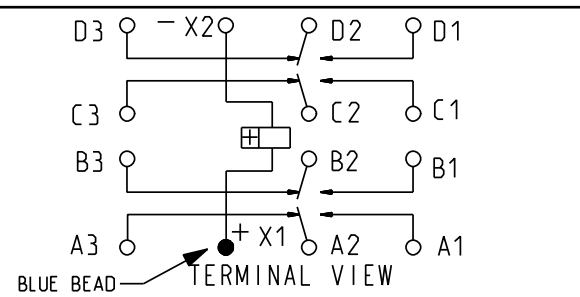

CONTACT RATING: LOW LEVEL
5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
100,000 OPERATIONS

DR. B.D. 30APR2008 CK. 5/9/08 J.M.B.

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM
CUST. NO. ---- REV. ---

TE NUMBER
1617761-6

CII PART NUMBER
FCB-405-CX2