


COIL: @ 25°C
 RESISTANCE 35 OHMS ± 10%
 NOMINAL VOLTAGE 6.3 VDC
 MUST OPERATE 3.2 VDC
 MUST RELEASE 0.35 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: _____

CUSTOMER DATA SHEET

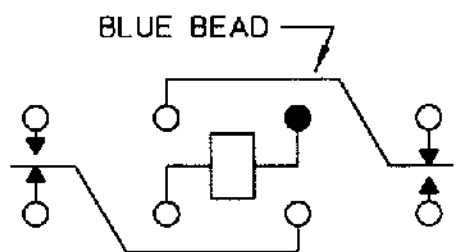

CONTACT RATING: 3 AMPS 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. R.B. 12/7/95 CK. 12/18/95 *[Signature]*



CUST. C. I. I. STD.
 CUST. NO. _____

TYPE "FW" RELAY

FW1220A00