

COIL: @ +25°C

RESISTANCE 700 OHMS ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 1.5 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS AT 30 g's

SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

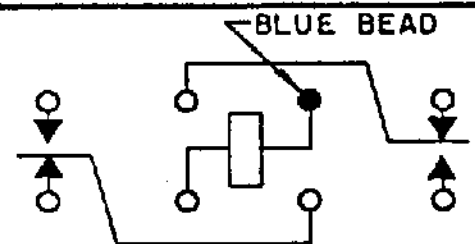

CONTACT RATING: Low Level
2 AMPS, 28 VDC 100,000
Operations

DR. 10-2-86

CK. JMB



**Communications
Instruments, Inc.**

CUST. CII STD.

CUST. NO. 39016/6-209P

TYPE HFW RELAY

HFW 1201 K46P