

REV. 0


DCO 16116

COIL: @ 25°C	
RESISTANCE	27 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.7 VDC
MUST RELEASE	1.65 VDC MAX, 0.29 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX
 CONTACT STABILIZATION 2.5 MS MAX
 ALL OTHER REQUIREMENTS TO MIL-R-39016 LEVEL P

CUSTOMER DATA SHEET

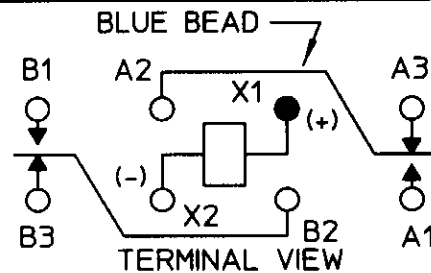

CONTACT RATING: LOW LEVEL TO
 2 AMPS 28 VDC RESISTIVE
 100,000 OPERATIONS

DR. B.D. 2/15/00 CK. *gqh* 2/15/00



HFW1201L01P

CUST. QPL
 CUST. NO. M39016/6-139P REV.

"HFW" RELAY