

COIL: @ 25°C


RESISTANCE 1030 Ω ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 11.4 VDC

MUST RELEASE 6.9 VDC MAX, 1.1 VDC MIN.

CUSTOMER DATA SHEET

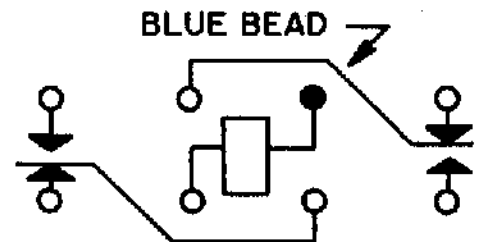

ENVIRONMENT:

VIBRATION 10 CPS TO 2500 CPS @ 20 g's

SHOCK 50 g's 6 MS.DURATION

TEMPERATURE -65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO 2 AMPS RESISTIVE 100,000 OPERATIONS

NOTES: _____

DR. R.B. 9-19-90 CK. 9/19/90 *[Signature]*



CUST. QPL
CUST. NO. M39016/44-028P

TYPE HMS RELAY

HMS1130S04P