


REV. 0
DCO 143333

COIL: @ 25°C	
RESISTANCE	4000 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.2 VDC
MUST RELEASE	8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 4.0 MS MAX.
	RELEASE TIME 2.5 MS MAX.
	CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

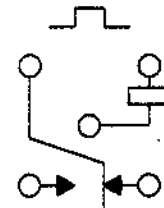

TERMINAL VIEW

CONTACT RATING:	LOW LEVEL TO 1A
	28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 11/29/01 CK [Signature] 11/30/01

CI Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M39016/10-024L REV.

"JIMS" RELAY

J1MSP-26XL