


REV. 0
DCO 140869

COIL: @ 25°C
 RESISTANCE 4000 OHMS \pm 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2 VDC
 MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4 MS MAX
RELEASE TIME 2.5 MS MAX
CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

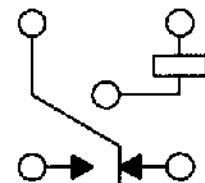

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 1/26/99 *CK* 1/26/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/10-023P

TYPE "J1MS" RELAY

J1MSW-26XP