

REV. 0
DCO 142077


COIL: @ 25°C
 RESISTANCE _____ 390 OHMS ± 10%
 NOMINAL VOLTAGE _____ 12.0 VDC
 MUST OPERATE _____ 7.0 VDC

 MUST RELEASE _____ 4.0 VDC MAX, 0.63 VDC MIN

ENVIRONMENT:
 VIBRATION _____ 10 _____ CPS TO _____ 3000 _____ CPS @ _____ 30 _____ g's
 SHOCK _____ 75 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -65 _____ °C TO _____ +125 _____ °C

NOTES: _____ OPERATE TIME 2.0 MS MAX.
 _____ RELEASE TIME 4.0 MS MAX.
 _____ CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

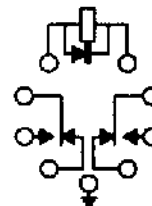

TERMINAL VIEW

CONTACT RATING: _____ LOW LEVEL TO 1A
 _____ 28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 6/6/00

Kerry C. 6/6/00

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. _____ OPL
 CUST. NO. M39016/15-091L REV. _____

JMAD RELAY

JMACDG-12XL