


REV. 0
DCO 141034

COIL:
 RESISTANCE 11,000 OHMS ± 10%
 NOMINAL VOLTAGE 48.0 VDC
 MUST OPERATE 25.8 VDC
 MUST RELEASE 13.0 VDC MAX, 2.4 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 7.5 MS MAX
CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

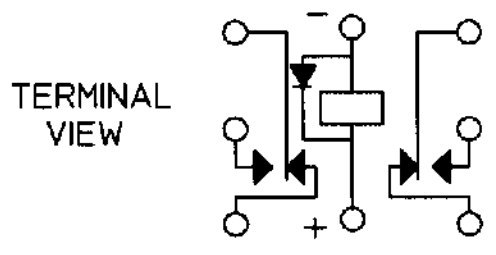

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. B.D. 4/28/99 *CK* *Gray* 4/28/99



CUST. QPL
 CUST. NO. M39016/42-038P TYPE JMGSD RELAY

JMGSCD-48P