

COIL: @ 25°C	
RESISTANCE	800 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
GATE TURN-ON	4.3 VDC MAX.
GATE TURN-OFF	0.5 VDC MAX.
MUST OPERATE	7.1 VDC
MUST RELEASE	4.0 VDC MAX, 0.65 VDC MIN.

ENVIRONMENT:		
VIBRATION	10	CPS TO 3000 CPS @ 30 g's
SHOCK	75	g's 6 MS. DURATION
TEMPERATURE	-65	°C TO +125 °C


NOTES:

OPERATE TIME 4.0 MS MAX.

RELEASE TIME 7.5 MS MAX.


CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

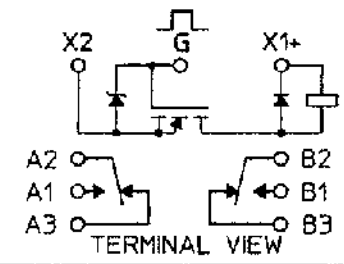

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

 DR. R.B. 11/19/97 CK. *[Signature]*



CUST. QPL

CUST. NO. M28776/7-010L REV. "JMGST" RELAY

JMGST-12LW