


REV. 1 8/25/98

COIL: @ 25°C	
RESISTANCE	3200 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
GATE TURN-ON	4.3 VDC MAX.
GATE TURN-OFF	0.5 VDC MAX.
MUST OPERATE	14.2 VDC
MUST RELEASE	8.0 VDC MAX, 1.30 VDC MIN.

CUSTOMER DATA SHEET

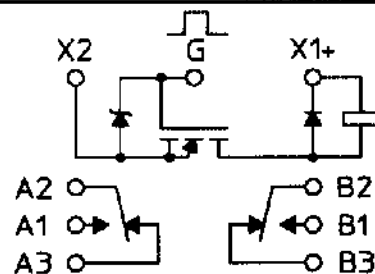

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT STABILIZATION 2.0 MS MAX.

DR. R.B. 12/16/97 *ER. Spey 8/25/98*



CUST. QPL
CUST. NO. M28776/7-006M TYPE *MGST* RELAY

JMGST-26M