


REV. 0
DCO 141030

COIL: @ 25°C
 RESISTANCE 1600 OHMS ±10%
 NOMINAL VOLTAGE 18.0 VDC
 MUST OPERATE 9.8 VDC
 MUST RELEASE 6.0 VDC MAX. 0.92 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 2.0 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

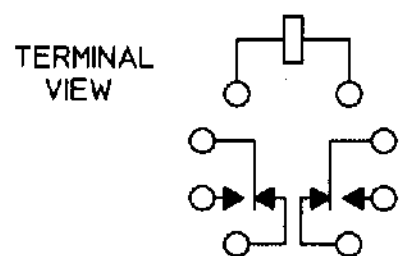

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 4/27/99 *CK* *ERRY* *4/28/99*

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/11-040L

TYPE "JMS" RELAY

JMSC-18XL