

REV. 0
DCO 142097


| | |
|-----------------|---------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 400 OHMS ±10% |
| NOMINAL VOLTAGE | 9.0 VDC |
| MUST OPERATE | 4.85 VDC |
| MUST RELEASE | 3.0 VDC MAX, .55 VDC MIN. |

ENVIRONMENT:

| | | | | | | |
|-------------|-----|--------|------|--------------|----|-----|
| VIBRATION | 10 | CPS TO | 3000 | CPS @ | 30 | g's |
| SHOCK | 75 | g's | 6 | MS. DURATION | | |
| TEMPERATURE | -65 | °C TO | +125 | °C | | |

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 7.5 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

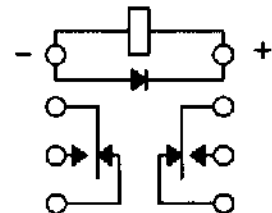

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. PBB 6/14/00 *CK JERRY* 6/14/00



CUST. QPL
CUST. NO. M39016/16-047L REV.

'JMSD' RELAY

JMSCD-9XLS