


REV. 0

DCO 142804

|                 |                           |
|-----------------|---------------------------|
| COIL: @ 25°C    |                           |
| RESISTANCE      | 400 OHMS ±10%             |
| NOMINAL VOLTAGE | 9.0 VDC                   |
| MUST OPERATE    | 6.1 VDC                   |
| MUST RELEASE    | 3.6 VDC MAX, 1.1 VDC MIN. |

|              |                                       |
|--------------|---------------------------------------|
| ENVIRONMENT: |                                       |
| VIBRATION    | 10 CPS TO 3000 CPS @ 30 g's           |
| SHOCK        | 75 g's 6 MS. DURATION                 |
| TEMPERATURE  | -65 °C TO +125 °C                     |
| NOTES:       | OPERATE TIME 4.0 MS MAX               |
|              | RELEASE TIME 7.5 MS MAX               |
|              | CONTACT STABILIZATION TIME 2.0 MS MAX |

CUSTOMER DATA SHEET

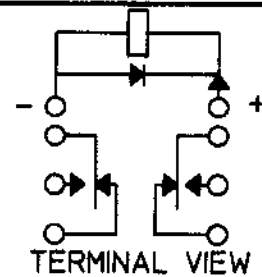

CONTACT RATING: LOW LEVEL TO  
1A 28 VDC RESISTIVE 100,000  
OPERATIONS

DR. PBB 3/9/01 *(Signature)* 3/4/01

**CH Technologies**  
advanced control electronic solutions

CUST. QPL  
CUST. NO. M39016/21-043M REV.

'JMSDD' RELAY

JMSCDD-9XMS