


REV. 1 3/24/98

COIL: @ 25°C  
 RESISTANCE 3300 OHMS ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE VOLTAGE 14.2 VDC  
 TURN-ON BASE CURRENT 0.06 mADC  
 MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 4.0 MS MAX  
TURN-OFF TIME 7.5 MS MAX  
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

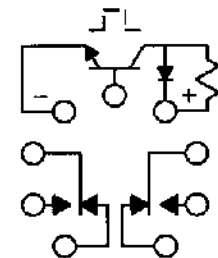

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 2/19/97 CK ERY 3/24/98

COMMUNICATIONS  
 INSTRUMENTS, INC.

CUST. OPL  
 CUST. NO. M28776/3-030L

TYPE JMST RELAY

JMSPT-26XL