


REV. 0
DCO 143385

COIL: @ 25°C	
RESISTANCE	850 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	4.0 VDC MAX, 0.64 VDC MIN.

CUSTOMER DATA SHEET

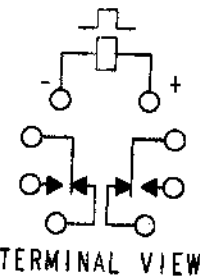

ENVIRONMENT:

VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:

OPERATE TIME	4.0 MS MAX.
RELEASE TIME	2.0 MS MAX.
CONTACT BOUNCE	1.5 MS MAX.

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 1/11/02 *[Signature]* 1/11/02

CII Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M39016/11-021L REV.

"JMS" RELAY

JMSW-12XL