

REV. 3 5/24/96

COIL:


RESISTANCE	90 OHMS
NOMINAL VOLTAGE	6.0 VDC
MUST OPERATE	3.0 VDC
MUST RELEASE	0.3 VDC

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	20	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: (LEVEL L ACCEPTANCE TESTING ONLY)

CUSTOMER DATA SHEET

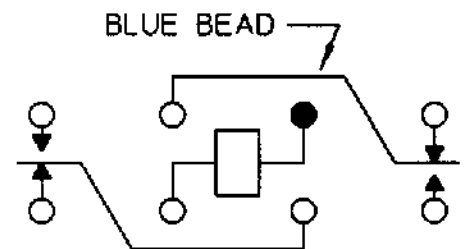

CONTACT RATING: 1 AMP 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/23/92 CK 5/24/96 RB

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/34-002

TYPE "MFW" RELAY

MFW1201S06