


REV. 0
DCO 142913

COIL: @ 25°C	
RESISTANCE	390 OHMS ±20%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	8.4 VDC
MUST RELEASE	-----

ENVIRONMENT:	
VIBRATION	10 CPS TO 500 CPS @ 10 g's
SHOCK	30 g's 6 MS. DURATION
TEMPERATURE	-55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

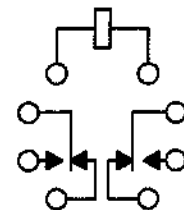

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 5/4/01

CK. 5400B



CUST. CII STD
CUST. NO. REV.

'MW3' RELAY
3GHZ

MW3-12A