


REV. 0  
DCO 143248

COIL: @ 25°C	
RESISTANCE	390 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	4.0 VDC MAX., 0.63 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	
OPERATE TIME	2.0 MS MAX.
RELEASE TIME	1.5 MS MAX.
CONTACT BOUNCE	1.5 MS MAX.

CUSTOMER DATA SHEET

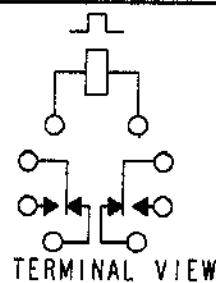

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 10/3/01 CK. *[Signature]*

**CII Technologies**  
advanced control electronic solutions

CUST. CII  
CUST. NO. STANDARD REV.

TYPE  
"MW3HP  
3GHZ" RELAY

MW3HP-12A