


REV. A  
DCO 144146

COIL: @ 25°C	
RESISTANCE	850 OHMS ±20%
NOMINAL VOLTAGE	12 VDC
MUST OPERATE	9.0 VDC
MUST RELEASE	

ENVIRONMENT:	
VIBRATION	10 Hz TO 500 Hz @ 10 g's
SHOCK	30 g's 6 MS. DURATION
TEMPERATURE	-55 °C TO +85 °C

NOTES: OPERATE TIME 6 MS MAX  
RELEASE TIME 3 MS MAX

CUSTOMER DATA SHEET

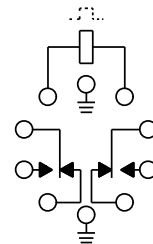

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 16JAN2006 CK. JERRY C. 1/17/06

**CII Technologies™**  
advanced control electronic solutions

CUST. C.I.I. STD.  
CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

MW4S RELAY  
4 GHZ

MW4S-12AEG