

REV. 0


DCO 141243

COIL: @ 25°C	
RESISTANCE	2300 OHMS ±10%
NOMINAL VOLTAGE	18.0 VDC
MUST OPERATE	10.5 VDC
MUST RELEASE	6.0 VDC MAX, 0.91 VDC MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		
NOTES:	OPERATE TIME 4.0 MS MAX					
	RELEASE TIME 2.5 MS MAX					
	CONTACT BOUNCE 1.5 MS MAX					

CUSTOMER DATA SHEET

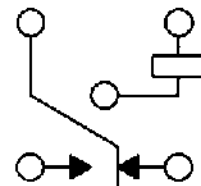

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/12/99 CK 8/12/99



CUST. C. I. I.
 CUST. NO. STANDARD REV.

"PR1MS" RELAY

PR1MSC-18X