

REV. 0
DCO 143759


COIL: @ 25°C	
RESISTANCE	100 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.6 VDC
MUST RELEASE	1.4 VDC MAX., 0.23 VDC MIN.

ENVIRONMENT:

VIBRATION	10 Hz	TO	3000 Hz	@	30 g's
SHOCK	75 g's		6 MS. DURATION		
TEMPERATURE	-65 °C	TO	+125 °C		

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 2.0 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

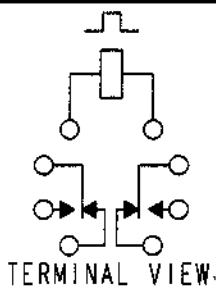

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 10JUN03 *EK* 6/11/03



CUST. _____
CUST. NO. COTS STD REV. _____

"PRMS" RELAY

PRMSP-5X