

COIL:


RESISTANCE 390 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 15.5 VDC @ 25°C
 MUST RELEASE 1.8 VDC @ 25°C

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: TERMINALS ARE GOLD-PLATED I.A.W.
MIL-G-45204, TYPE II, CLASS I.
OPERATE & RELEASE TIME 5 MS MAX.
CONTACT BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

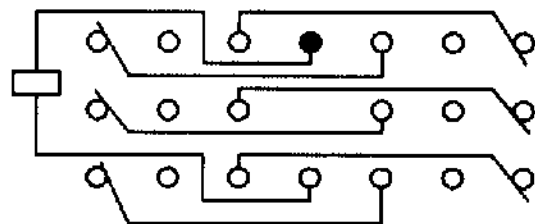

CONTACT RATING: LOW LEVEL TO
2 AMP / 28 VDC

DR. R.B. 11/4/91 CK. JAW/ 11-4-91



CUST. CIISIO
 CUST. NO. _____

TYPE 'SS' RELAY

SSBW-6C-24G