 


Heavy Duty Sealed Connector Series

 
Housings & Headers

Configurations


Group A Size Configurations



2 Position
2 size 1.5K




2 Position
2 size 2.8

 


3 Position
3 size 1.5K

Group B Size Configurations

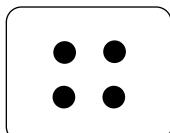


4 Position
4 size 2.8

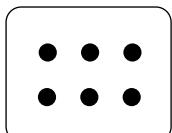


6 Position
6 size 1.5K


Group C Size Configurations

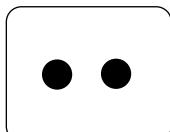


2 Position
2 size 6.3

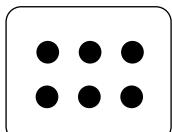

6 Position
6 size 2.8

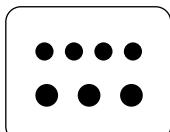


7 Position
4 size 1.5K,
3 size 2.8

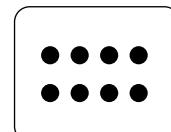


8 Position
8 size 1.5K


Group D Size Configurations

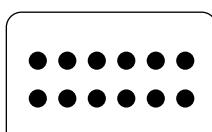

12 Position
12 size 1.5K

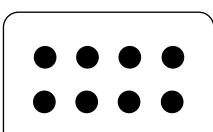


8 Position
8 size 2.8

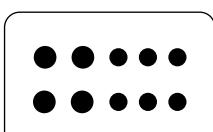


10 Position
6 size 1.5K,
4 size 2.8


Group E Size Configurations

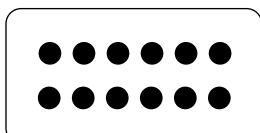


12 Position
12 size 2.8

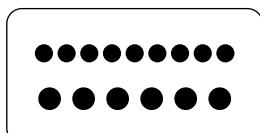


15 Position
9 size 1.5K,
6 size 2.8

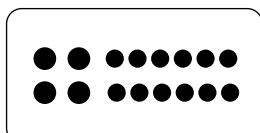

16 Position
12 size 1.5K,
4 size 2.8

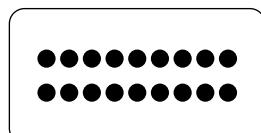

18 Position
12 size 1.5K

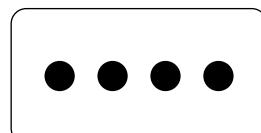

4 Position
4 size 6.3