



产品认证证书

证书编号: CQC18002202082

发证日期: 2024年05月08日
有效期至: 2029年05月07日

委托人名称 泰科电子(深圳)有限公司
及注册地址 深圳市宝安区石岩街道泰科电子科技园

制造商名称 泰科电子(深圳)有限公司
及注册地址 深圳市宝安区石岩街道泰科电子科技园

生产企业名称 泰科电子(深圳)有限公司
及生产地址 深圳市宝安区石岩街道泰科电子科技园

产品名称和系列、规格、型号 继电器
OJT 系列 触点负载: 5A 250VAC/30VDC (DM/LM), 10A 250VAC(HM); 线圈(DM/LM): 3VDC、5VDC、6VDC、9VDC、12VDC、18VDC、24VDC、48VDC, 线圈(HM): 5VDC、12VDC、24VDC; 0.45W 或 0.25W; 电气寿命: 20000 周期 (DM/LM, 250VAC) 10000 周期 (DM/LM, 30VDC), 10000 周期 (HM/ 250VAC/-30°C~85°C), 30000 周期 (HM/ 250VAC/-30°C~25°C); 机械寿命: 200000 周期; 环境温度: -30°C~70°C 或 -30°C~85°C; RTII、RTIII,系列描述见附件(仅适用于海拔 5000 米及以下)

产品标准和技术要求 GB/T 21711.1-2023

认证模式 产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC11-462155-2010 认证规则的要求, 特发此证。
本证书为变更证书, 证书首次颁发日期: 2018 年 10 月 12 日
证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站 (www.cnca.gov.cn) 查验证书信息



签发: 谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE





产品认证证书

证书编号: CQC18002202082


第 1 页 / 共 1 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号:

系列命名规则:

OJT	-**	-1	**	**	*	*****
代码: 6 位数字或字母代码						
绝缘等级: 空白或 F 或 WG: F 级 155						
线圈功耗: DM - 450mW LM - 250mW HM- 450 mW						
线圈电压: 03:3V 05:5V 06:6V 09:9V 12:12V 18:18V 24:24V 48:48V (HM 仅包含 5V 12V 24V 线圈电压)						
极 数: 1: 单极						
密封结构: SS: 有通气孔; SH: 外壳点胶密封 (HM 仅包含 SS 型, 有通气孔)						
产品基本型号: OJT						

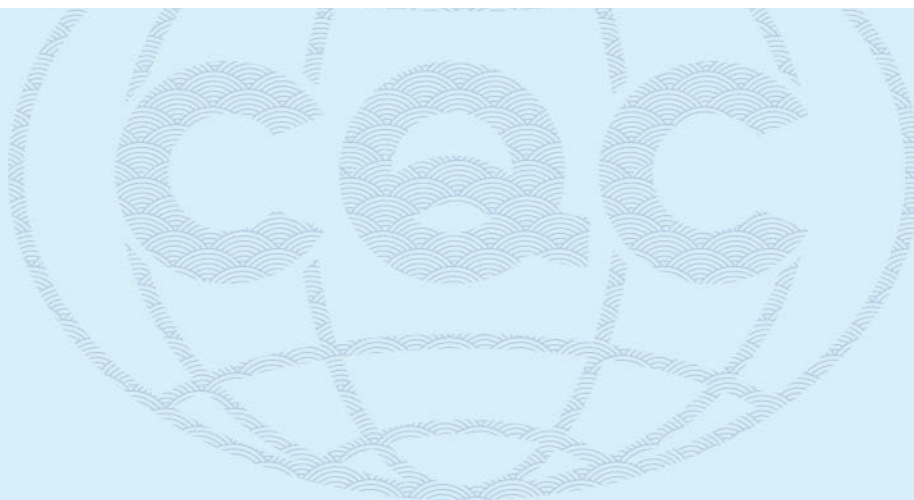

中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE



CERTIFICATE OF PRODUCT CERTIFICATION

CERTIFICATE NO.: CQC18002202082

Valid from: May.08,2024

Valid until:May.07,2029

NAME AND REGISTERED ADDRESS OF THE APPLICANT Tyco Electronics (shenzhen) Co., Ltd
Tyco Electronics Technology Park,Shiyan Town,Baoan District,Shenzhen, Guangdong, P.R.China

NAME AND REGISTERED ADDRESS OF THE MANUFACTURER Tyco Electronics (shenzhen) Co., Ltd
Tyco Electronics Technology Park,Shiyan Town,Baoan District,Shenzhen, Guangdong, P.R.China

NAME AND LOCATION OF THE FACTORY Tyco Electronics (shenzhen) Co., Ltd
Tyco Electronics Technology Park,Shiyan Town,Baoan District,Shenzhen, Guangdong, P.R.China

PRODUCT NAME, MODEL AND SPECIFICATION Relay
OJT series Contact load : 5A 250VAC/30VDC (DM/LM), 10A 250VAC(HM) ; coil voltage (DM/LM) : 3VDC, 5VDC, 6VDC, 9VDC, 12VDC, 18VDC, 24VDC, 48VDC, coil voltage (HM) : 5VDC, 12VDC, 24VDC ; 0.45W or 0.25W ; Electrical endurance : 20000 cycles (DM/LM, 250VAC) 10000 cycles (DM/LM, 30VDC) , 10000 cycles (OJT-SS-1**HM/ 250VAC/-30°C~85°C) , 30000 cycles(OJT-SS-1**HM/250VAC/room) ; Mechanical encurance : 200000 cycles ; Ambient temperature : -30°C~70°C or -30°C~85°C ; RTII, RTIII, series description see annex(Only applicable to 5000 meters above sea level and below)

THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS GB/T 21711.1-2023

TYPE OF CERTIFICATION SCHEMES Type Testing of Product + Initial Factory Inspection + Follow up Factory Inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC11-462155-2010.

Date of original issued: Oct.12,2018

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

The certificate information is available through the QR code below or CNCA's website: www.cnca.gov.cn



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE



CHINA QUALITY CERTIFICATION CENTRE CO., LTD.
Section 9, No. 188, Nansihuan Xilu, Beijing 100070 P. R. China

Tel: +86 10 83886666
<http://www.cqc.com.cn>



CERTIFICATE OF PRODUCT CERTIFICATION

CERTIFICATE NO. : CQC18002202082

page 1 of 1

paper:

This certificate and attachments shall be used at the same time, and the verification instructions can be found in the main certificate.

系列命名规则:

OJT	-**	-1	**	**	*	*****
代码: 6 位数字或字母代码						
绝缘等级: 空白或 F 或 WG: F 级 155						
线圈功耗: DM - 450mW LM - 250mW HM- 450 mW						
线圈电压: 03:3V 05:5V 06:6V 09:9V 12:12V 18:18V 24:24V 48:48V (HM 仅包含 5V 12V 24V 线圈电压)						
极 数: 1: 单极						
密封结构: SS: 有通气孔; SH: 外亮点胶密封 (HM 仅包含 SS 型, 有通气孔)						
产品基本型号: OJT						



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE