


Circuit Diagram

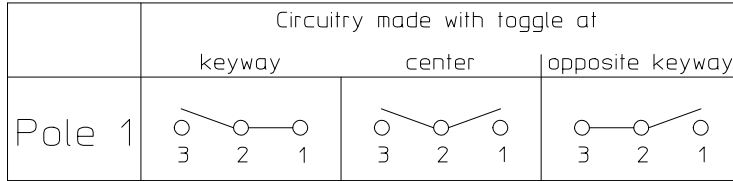

Actuation

- locking keyway side
- locking center position
- locking opposite keyway side

for customer
 release 20.09.2019

Construction

- Material, Casing Thermoplast GF
- Material, Cover GD-ZnAl4Cu1
- Connections Faston DIN 46 244-A6,3-0,8
- Protection Interior IP 65 IEC 60529
- Connections IP 00 IEC 60529

Mechanical Data

- Current carrying parts CuZn-Alloy
- Contacts Ag
- Ambient Temperature Range -40°C to +85°C
- Storage Temperature Range -40°C to +85°C
- Life Cycle (nominal Load) 100.000 operations

Electrical Data

- Voltage 12 V DC ohmic Load 20A
- 28 V DC ohmic Load 20A
- 28 V DC inductive Load at L/R = 5 ms 15A
- 28 V DC lamp Load 5A

Min. Rating 12 V DC, 20 mA

It is recommended to use gold-plated contacts
for lower currents or voltages.

For this drawing we reserve the copyright in accordance with DIN ISO 16016

	Date	Name	mm ↔	Scale 1:1		Drawing No:
Create	17.09.2019	Stock				General Tolerances DIN ISO 2768 cL
Edited	20.09.2019	Walza	NSN.:			
Check	20.09.2019	Stock				