



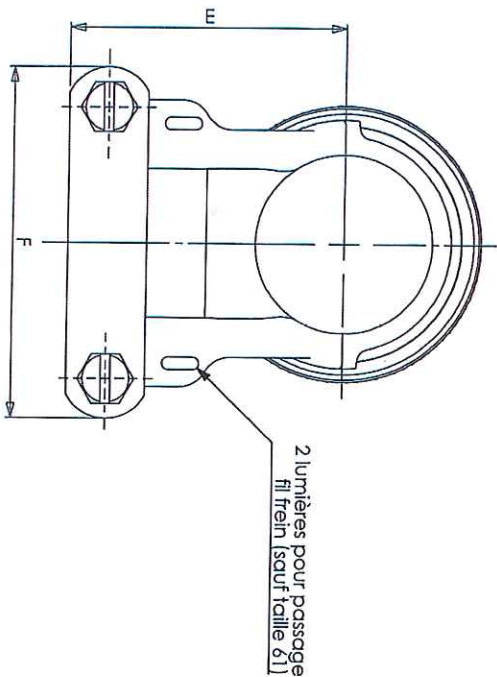

Matériau : acier inoxydable passivé

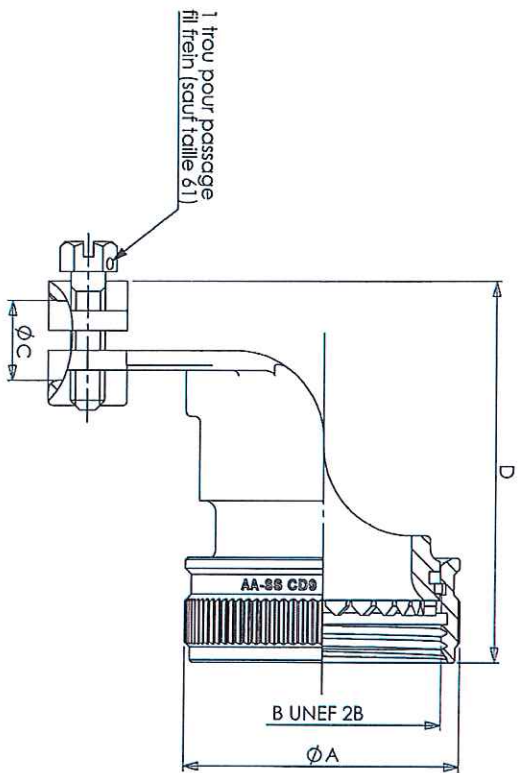

Taille **	Ø A max.	B UNEF 2B	Ø C		D		E max.	F max.
			mini	Maxi	mini	Maxi		
07	21,05	3/4" - 20	3,60	13,70	25,60	35,70	22,60	23,85
12	24,55	7/8" - 20	5,70	15,80	26,00	36,10	24,10	26,85
19	28,05	1" - 20	6,00	15,60	36,00	46,10	28,10	35,85
27	29,55	1 1/16 - 18	6,00	15,60	36,00	46,10	28,10	35,85
37	32,55	1 3/16 - 18	9,20	19,30	36,50	48,70	34,10	38,35
61	40,55	1 1/2 - 18	28,50	34,30	47,70	53,50	33,20	42,50

b	31/08/2017	CE14077
d	15/07/2008	0222078
Revision	Date	Observations

ORIGINE :
Raccord coudé

SERIE DCIN
DESIGNATION

DATE 31/08/2017

REF : 119-0392-XX

USA Creation
USA Approval

TE
Connecteurs Electriques Deutsch
17, rue Lavoisier - BP 117 - 27081 EVREUX CEDEX 09 - FRANCE

TECHNICAL DATA SHEET

VERSION : REVISION
204-119-C101