

LOC		DIST		REVISIONS													
DF		-		P		LTR		DESCRIPTION				DATE		OWN		APVD	
				A				RELEASED PER ECO-11-000354				12JAN2011		RL		RPW	
				B				REV PER ECO-11-011392				09JUN2011		RJM3		DM	

ONLY

D

C

B

A

STRAIN RELIEF CLAMP
THERMOPLASTIC
PACKAGED UNASSEMBLED

#2-56 CAPTIVE SCREW
STAINLESS STEEL
QTY 4

WIRE TIE, SHOWN FOR REFERENCE ONLY
CUSTOMER SUPPLIED


2.607
REF

.296±.002


RECEPTACLE SHELL
NICKEL PLATED
ALUMINUM ALLOY

#4-40 JACKSCREW
STAINLESS STEEL
QTY 2

- △ CONNECTOR KIT INCLUDES QUADRAX CONTACTS (TYCO PART# 1445692-3, QTY 4) FOR 100Ω CABLE.
2. RECOMMENDED CABLES :
RAYCHEM, CEC-RWC-18687, CEC-RWC-18664
TENSOLITE, NF24Q100, NF26Q100.
- △ CONNECTOR IS MARKED WITH TYCO ELECTRONICS PART NUMBER, TYCO ELECTRONICS LOGO, CAGE CODE & DATE CODE.
4. OPERATING TEMPERATURE RANGE: -65°C TO 125°C (-85°F TO 257°F).
5. SILVER PLATED, STAINLESS STEEL RETENTION CLIPS ARE INSTALLED IN THE CONNECTOR.

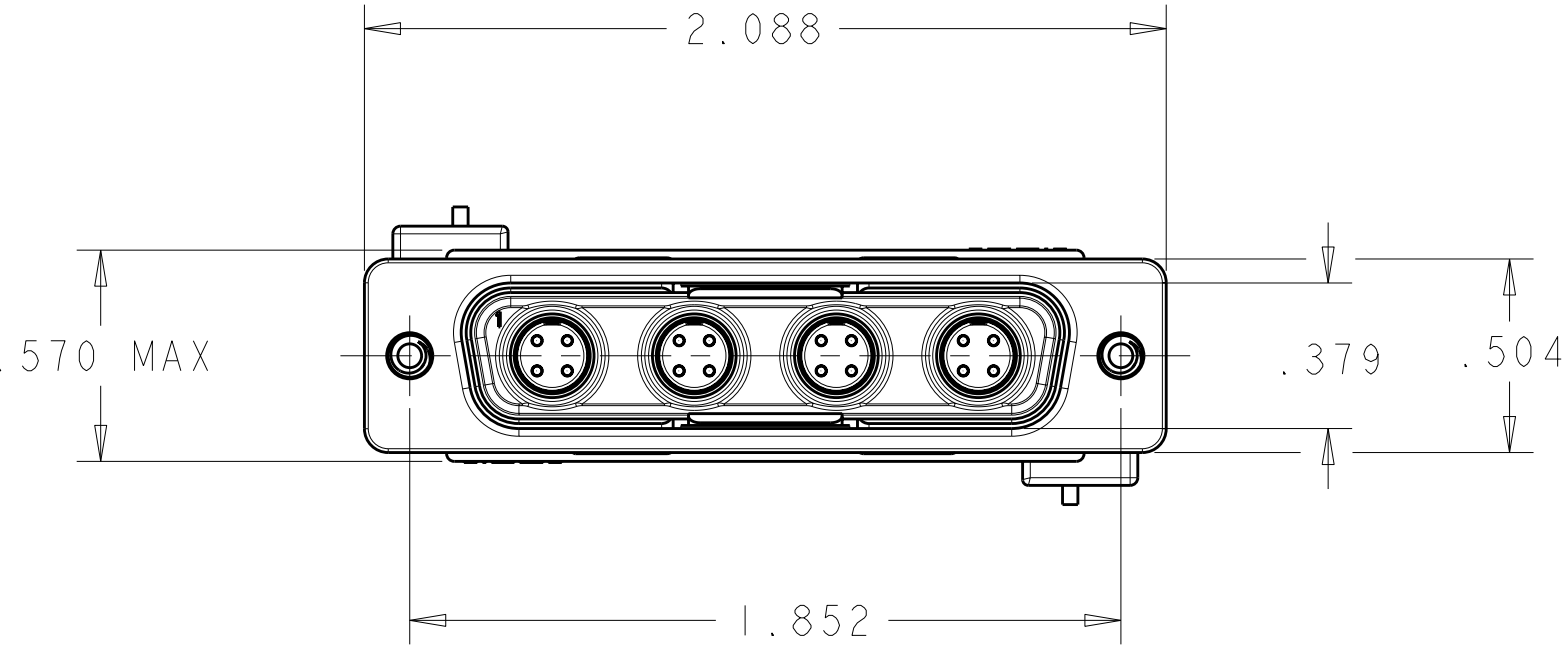

INTERFACIAL SEAL
FLUOROSILICONE

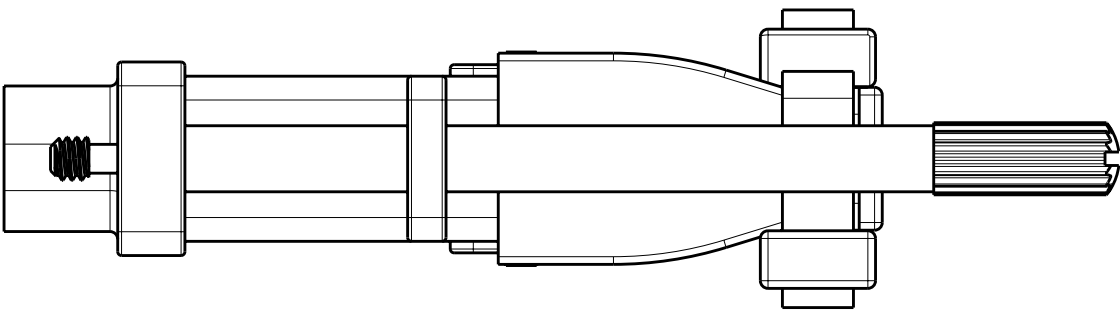

D

C

B

A

THIS DRAWING IS A CONTROLLED DOCUMENT.										2000263-1	
DIMENSIONS: IN										PART NUMBER	
TOLERANCES UNLESS OTHERWISE SPECIFIED: 9 PLC ±.01 3 PLC ±.01 5 PLC ±.005 4 PLC ±.01 ANGLES ±.1 FINISH -											
MATERIAL: -											
CUSTOMER DRAWING										SCALE 2:1 SHEET 1 OF 1 REV B	
DWN: D. FABIAN 10MAY2007 CHK: R.P. WALTER 27OCT2009 APVD: B. JOHN 28OCT2009											
PRODUCT SPEC											
APPLICATION SPEC											
WEIGHT: -											
SIZE: A1 CAGE CODE: C=2000263 DRAWING NO: 100779											
RESTRICTED TO: -											
KIT, RECTANGULAR QUADRAX 404 LOW PROFILE SIZE 3 RECEPTACLE											
TE Connectivity											