

THIS DRAWING IS UNPUBLISHED.

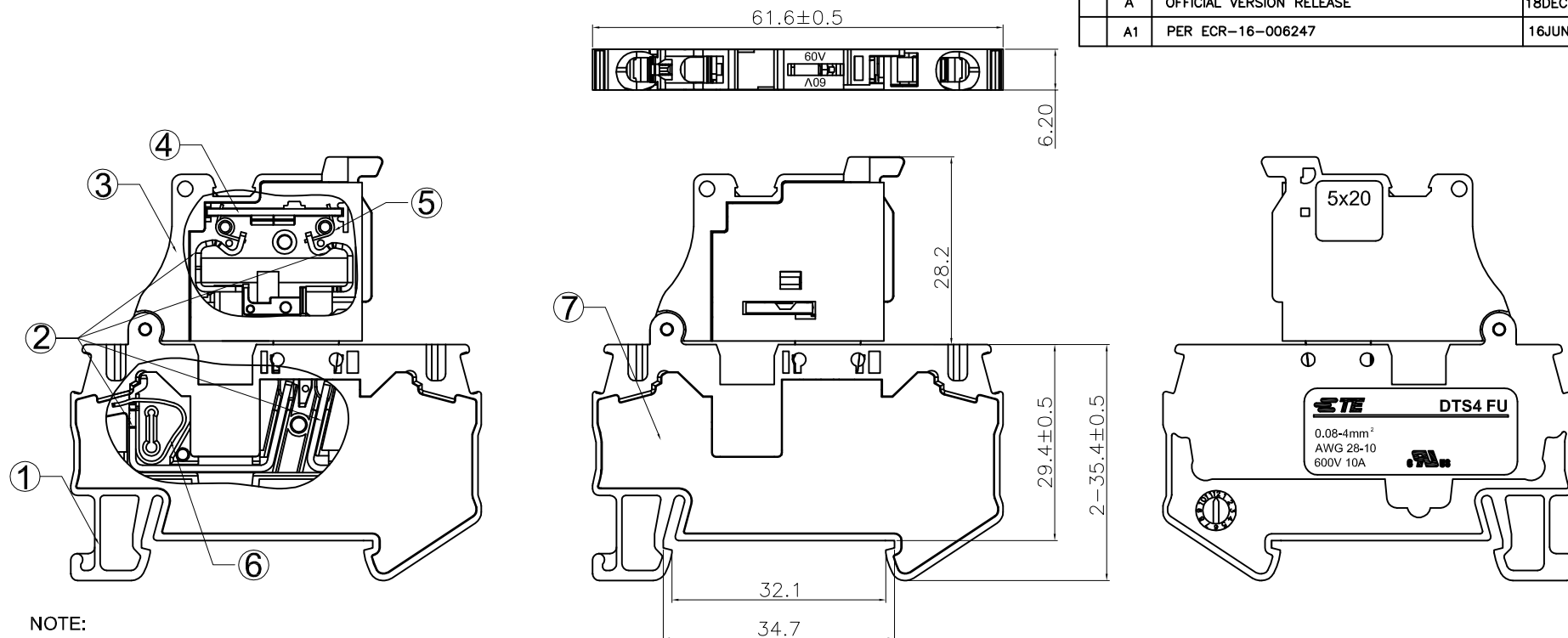
RELEASED FOR PUBLICATION

ALL RIGHTS RESERVED.

© COPYRIGHT - By -

REVISIONS

P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	OFFICIAL VERSION RELEASE	18DEC2015	F.Y	X.X
	A1	PER ECR-16-006247	16JUN2016	F.Y	X.X


 


NOTE:

1. Material: See Table
2. Rated current & voltage : 10Amp ,60V(follow LED)
3. Rated surge voltage: 4KV
4. Operation temperature : -40°C to +105°C
5. Wire strip length: 8mm -10mm
6. Suitable wire size : 28 - 10 AWG
7. Fuse: G/5x20
8. Requirement for environmental substance must be compliance with ROHS and REACH.
9. Recommended support rail requirements refer to 114 application specification.

7	COVER	THERMOPLASTIC	1	
6	SPRING CLAMP	STAINLESS STEEL	2	
5	SPRING	COPPER ALLOY	2	
4	LED MODULE	/	1	
3	HOUSING 2	THERMOPLASTIC	1	
2	TERMINAL	COPPER	4	TIN PLATED
1	HOUSING 1	THERMOPLASTIC	1	
ITEM	COMPONENTS	MATERIAL	Q'TY	PLATING

DTS4 FULED 60	2271584-1	BLACK
TE SERIES No.	PART NUMBER	COLOR

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN FENCER YU 16JUN2016	 TE Connectivity	
		CHK KOBBOY ZHAO 16JUN2016		
DIMENSIONS: mm		APVD XIANG XU 16JUN2016	NAME	
		PRODUCT SPEC	4mm~2 WIRE 1 IN 1 OUT SPRING CLAMP	
		APPLICATION SPEC	TERMINAL BLOCK ,FUSE TYPE WITH LED	
MATERIAL		114-137138	SIZE	RESTRICTED TO
FINISH		14.55 g	CAGE CODE	
		CUSTOMER DRAWING	SCALE	
			SHEET	
			REV	