

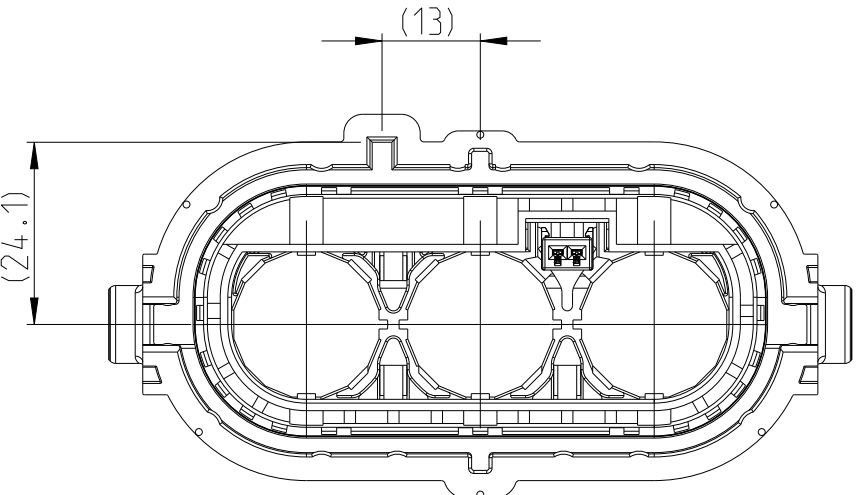
 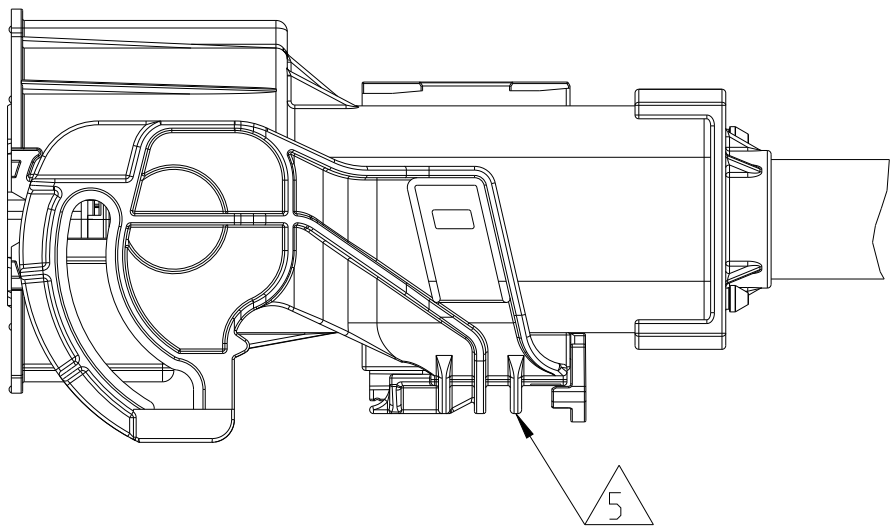


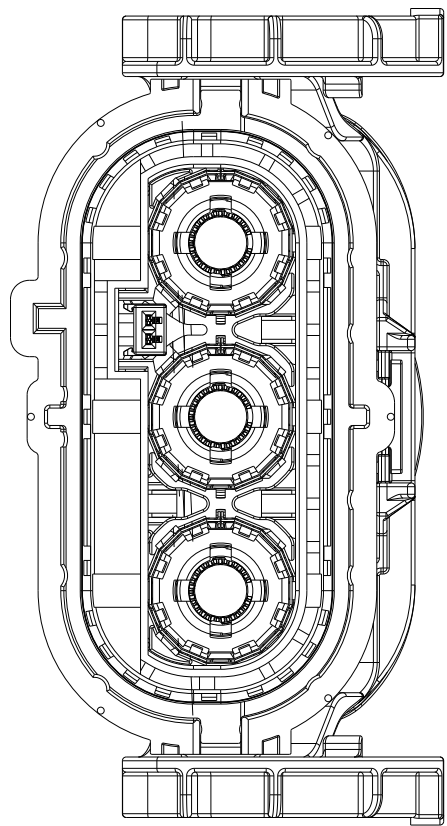

	TE PART NO.	REV.	LENGTH L [mm]	TOL. [mm]	CODING	LEVER POSITION
-	5-2286935-0	G	500	+30	A	TS
OBSOLETE	5-2286935-1	F	1000	+30		
OBSOLETE	5-2286935-2	F	2000	+35		
OBSOLETE	5-2286935-3	F	3000	+40		
OBSOLETE	5-2286935-4	F	4000	+50		
OBSOLETE	5-2286935-5	F	5000	+60	B	TS
OBSOLETE	6-2286935-0	F	500	+30		
OBSOLETE	6-2286935-1	F	1000	+30		
OBSOLETE	6-2286935-2	F	2000	+35		
OBSOLETE	6-2286935-3	F	3000	+40		
OBSOLETE	6-2286935-4	F	4000	+50	C	TS
OBSOLETE	6-2286935-5	F	5000	+60		
OBSOLETE	7-2286935-0	D	500	+30		
OBSOLETE	7-2286935-1	D	1000	+30		
OBSOLETE	7-2286935-2	D	2000	+35		
OBSOLETE	7-2286935-3	D	3000	+40	D	TS
OBSOLETE	7-2286935-4	D	4000	+50		
OBSOLETE	7-2286935-5	D	5000	+60		
OBSOLETE	8-2286935-0	D	500	+30		
OBSOLETE	8-2286935-1	D	1000	+30		
OBSOLETE	8-2286935-2	D	2000	+35	D	TS
OBSOLETE	8-2286935-3	D	3000	+40		
OBSOLETE	8-2286935-4	D	4000	+50		
OBSOLETE	8-2286935-5	D	5000	+60		



LABEL LEGEND:

 CURRENT REV. _____

TE PN: X-2286935-Y Rev. ____

DD/MM/YY _____ DATE CODE _____

2.7 kV DC TEST PASSED

- | | | | | | |
|------------|------------|------------|------------|--|------------|
| 1 | 1 | 1 | 1 | LABEL, HELL, TYP 323, 25.4 x 95.25 | 11 |
| see table | see table | see table | see table | 1 POS. POWER CABLE, 25 SQMM | 10 |
| 3 | 3 | 3 | 3 | SHIELDING SLEEVE, 180 DEG | 9 |
| 3 | 3 | 3 | 3 | INSULATION INSERT, 180 DEG | 8 |
| 3 | 3 | 3 | 3 | 8 MM HV. CONTACT, ASSY | 7 |
| 3 | 3 | 3 | 3 | PROTEC. COVER 8 MM HV, 90 DEG. 25 SQMM | 6 |
| 3 | 3 | 3 | 3 | SINGLE WIRE SEAL, 8 MM HV, 90 DEG. 25 SQMM | 5 |
| 3 | 3 | 3 | 3 | SHIELDING CRIMP FERRULE, 180 DEG OUTER | 4 |
| 3 | 3 | 3 | 3 | PROTECTION CAP, 180 DEG | 3 |
| 3 | 3 | 3 | 3 | SHIELD CRIMP FERRULE, 180 DEG INNER | 2 |
| 1 | - | - | - | 3 POS. 8 MM HV, REC HSG, 180 DEG. ASSY. SEALED, COD D (TS) | 1 |
| - | 1 | - | - | 3 POS. 8 MM HV, REC HSG, 180 DEG. ASSY. SEALED, COD C (TS) | |
| - | - | 1 | - | 3 POS. 8 MM HV, REC HSG, 180 DEG. ASSY. SEALED, COD B (TS) | |
| - | - | - | 1 | 3 POS. 8 MM HV, REC HSG, 180 DEG. ASSY. SEALED, COD A (TS) | |
| QTY
8-x | QTY
7-x | QTY
6-x | QTY
5-x | DESCRIPTION | ITEM
NO |

4805 (3/13)