


TWO CONDUCTOR CABLE, RADIATION CROSSLINKED, MODIFIED FLUOROPOLYMER INSULATED,  
150°C, 600 VOLT, LIGHTWEIGHT

The complete requirements for procuring the wire described herein shall consist of this document.

**Component wire -**  
55A0111

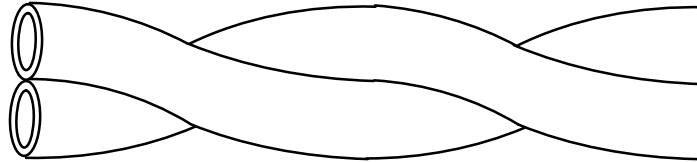

Part Description	Wire Size AWG	Outside Diameter (mm)		Maximum Weight (kg/ km)
		Target	Max	
55CD0265-28-*/*	28	1.37	1.47	2.88
55CD0265-26-*/*	26	1.63	1.73	4.53

**COLOUR CODE:** The '\*' in the part description shall be replaced by colour code designators with a slash separating component wire colours:  
e.g. 55CD0265-26-2/6, size 26, cores red, blue.

**PERFORMANCE REQUIREMENTS:** This product shall meet all the requirements of the issue in effect of 55A0121 except that:  
the lay direction shall be right hand  
the lay length shall be 6±1 mm.

**APPROVAL:** Electronic sign off - no signatures will appear.