


SIX CONDUCTOR CABLE, MODIFIED FLUOROPOLYMER INSULATED, SHIELDED AND JACKETED,
 LIGHTWEIGHT, 135°C, 600 VOLT

The complete requirements for procuring the product described herein shall consist of this document.

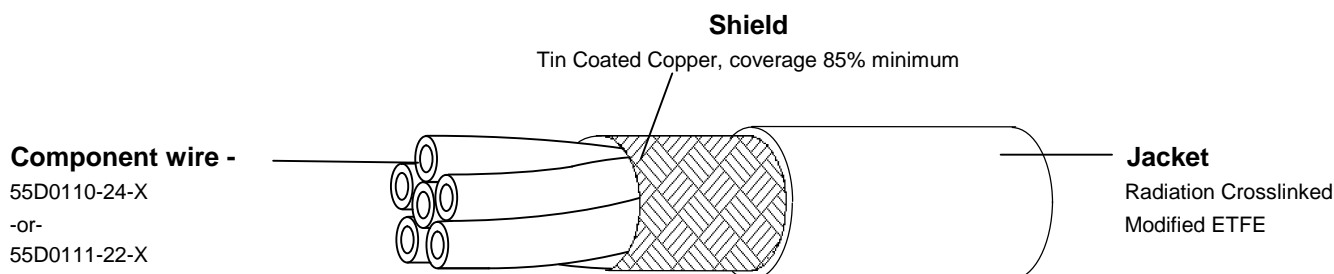

Part Description	Wire Size	Shield Size (mm)	Jacket Thickness (mm) Min.	Outside Diameter (mm)		Target Weight (kg/km)	Maximum Weight (kg/km)
				Target	Max.		
55CD0309-24-9/6/3/5/2/0-9	24	0.13	0.15	3.50	3.68	28.00	30.96
55CD0309-22-9/6/3/5/2/0-9	22	0.13	0.15	4.02	4.22	38.26	41.82

COLOUR CODE: Standard colour code designator in accordance with Mil Std 681.
 e.g. 55CD0309-22-9/6/3/5/2/0-9,
 colours white, blue, orange, green, red, black, jacket white.

PERFORMANCE REQUIREMENTS: Component wire to be tested to and meets the requirements of the issue in effect of Def Stan 61-12(Part 33) and Supplement 001, Table 4.

Except as stated above, this product shall meet and be tested to the issue in effect of 55A1161 SCD.

MARKING REQUIREMENT: Every 400 ± 100 mm.
 Mark shall be, e.g. 55CD0309-XX K1010 V

Where: "XX" = AWG size from part description.
 "K1010" = Cage Code
 and "V" = the Year Code in accordance with the table below

Code:	11	12	13	14	15	16	17
Year:	2011	2012	2013	2014	2015	2016	2017

APPROVAL: Electronic sign off - no signatures will appear.